



NOVUX™ Specialty Range Closure



Agility and flexibility for the networks of today and tomorrow

Introducing the new NOVUX™ Specialty Range Closure

The NOVUX Specialty Range Closure is a modern drop solution which gives providers the agility and flexibility to use it in last-mile fiber network applications, both above and below ground. Designed with the latest state of the art technology, the SRC100 is protected from harsh conditions by CommScope's new gel seal, Octopus™. Octopus simplifies re-entry for field installers and gives peace of mind to service providers.

Features and benefits

- **Capacity:**
 - Up to 48 fiber splices
 - 1 splitter
 - 4 ports
 - 8 cables (double stacking not to exceed 6.2 mm)
- **Adapters:**
 - 2 SC simplex
 - 2x LC duplex
- Accepts round or flat drop cables, or blown fiber tubes
- **Port size:**
 - 1 to 8 mm, 0.04 to 0.32 in round cables
 - 8 x 4.5 mm, 0.32 x 0.18 in flat cables
- Air valve option (via port) with 6 cables (double stacking)
- **Color:** black RAL9005 and gray
- **Security:** lead wire through eye hole, 4 positions
- **Dimensions:** 267 x 117 x 49 mm, 10.5 x 4.6 x 2 in, with integrated pole mounting features on the back side (length x width x height)
- IP68 2-meter water head, 20kPa
- Tested to IEC 60529
- Integrated pole mounting features

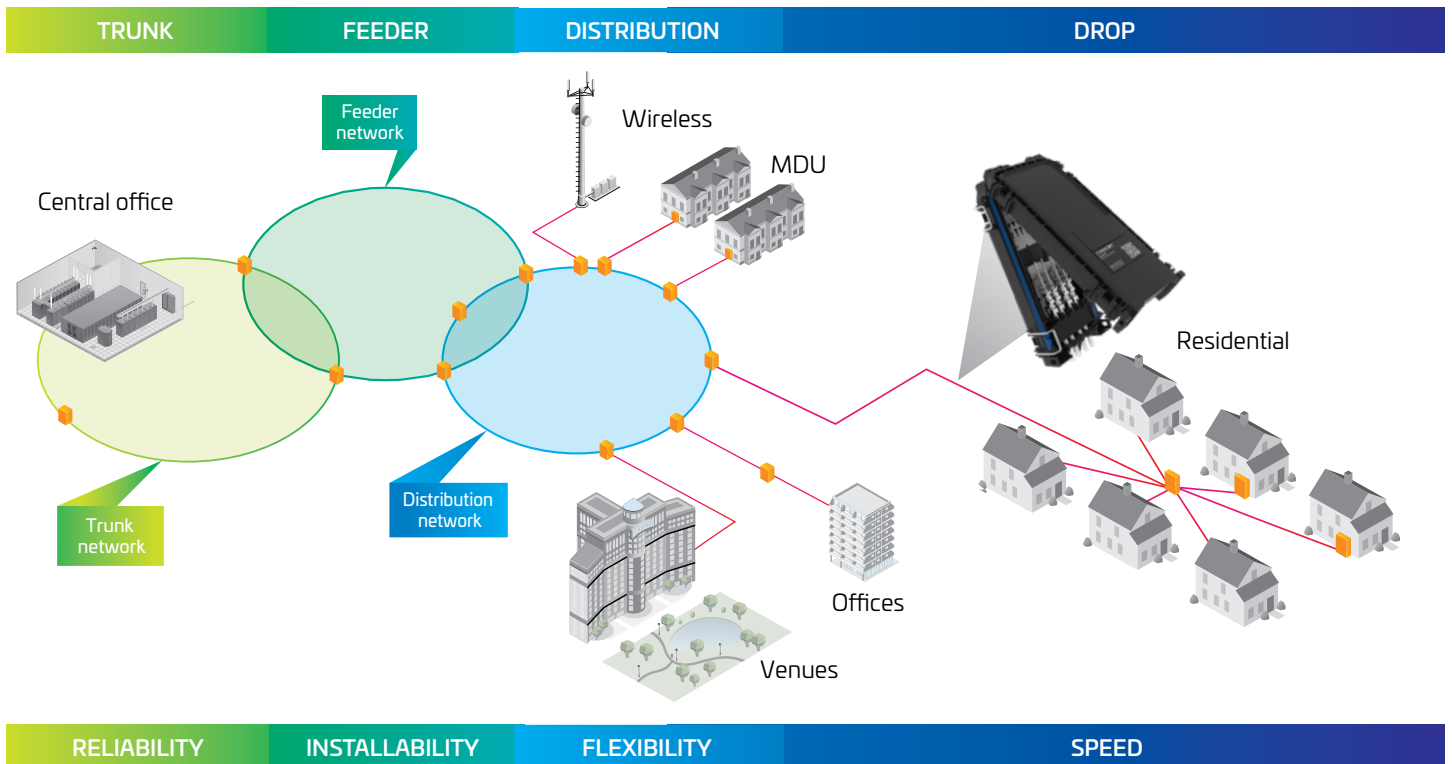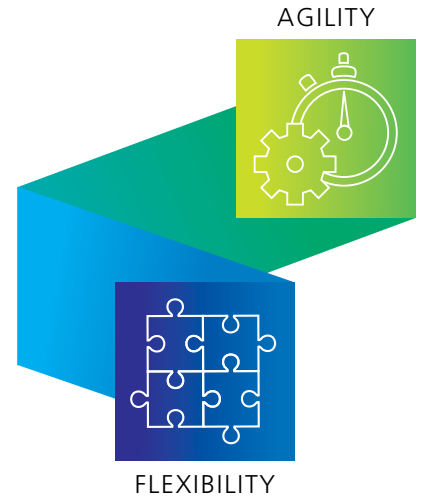

Ready for the field workforce of the future

We've designed the NOVUX SRC100 to be ready for the field, and ready for your workforce. With factory-installed hinges and a cover which opens from the bottom, the closure gives installers speed and ease of access. The SRC100 mounts easily onto flat surfaces or poles, thanks to built-in mounting tabs and straps. Security is provided by use of lead wire.

The SRC100 is protected from the environment by CommScope's state-of-the-art Octopus™ gel seal. A highly adaptable protective barrier, Octopus is extremely conformable and resilient in a wide range of harsh conditions. Octopus gel seal allows field technicians easy entry for upgrades or maintenance, even after numerous closure accesses.

Unique network identification

One-click access to all product information: each NOVUX hardened terminal comes with a QR code that allows field installers to access CommScope's cTrak app. With one click, cTrak provides a wealth of product information, specifications, installation instructions, videos, schematics, and test results.



NOVUX—built for you

You work hard to provide your customers with the best network connectivity. Why should your terminals look the same as those of other providers? NOVUX hardened terminals offer an optional customer-configurable ID plate, for ease of network record keeping, and clarity for multiple operators sharing locations.



NOVUX™ Specialty Range Closure ordering information

SRC -U 000

Size and color	
3	100 Black
4	100 Gray

Sealing	
U	Underground, IP68

Connector type	
1	SC/UPC
2	LC/UPC
3	SC/APC
4	LC/APC
5	Splice only

Number of adapters	
A	None
K	1
B	2

Cable retention	
*	See complete details at the bottom of the page.

Splice protector	
A	SMOUV 30
B	SMOUV 45
C	ANT






Splitters	
1	None
2	1:2
3	1:4

Number of splices	
B	12
C	24
E	48

Number of pigtails	
1	None
A	1
2	2
B	3
3	4

* Cable retention ¹	
A	None
B	NVX-CR-MC-FT-NN
C	NVX-CR-MC-RD-NN
D	NVX-CR-SA-SM-NN
E	NVX-CR-TI-SM-NN
F	NVX-CR-DU-SL-NN

¹ 2 cable attachments are supplied.

Cable Termination Unit (CTU) options				
				
NVX-CR-SA-SM-NN	NVX-CR-TI-SM-NN	NVX-CR-DU-SL-NN	NVX-CR-MC-RD-NN	NVX-CR-MC-FT-NN
<ul style="list-style-type: none"> Round cable Dia up to 8 mm Strength member Aramide yarns Single layer 	<ul style="list-style-type: none"> Round cable Dia up to 8 mm Aramide yarns Single layer 	<ul style="list-style-type: none"> Round cable Dia up to 6.2 mm Aramide yarns Dual layer Compact length 	<ul style="list-style-type: none"> Round cable Metal clip Range 4 to 6.2 mm 	<ul style="list-style-type: none"> Flat cable Metal clip Range 3 x 5 to 4 x 8 mm

Contact your CommScope representative for configuration availability.

Configurations available for order

SRC3-U5A1B1BB000 • SRC 100, black version, underground
MID: 760251022

- No adapters
- Splice only
- 12x SMOUV 45 splice
- No splitter
- 2x NVX-CR-MC-FT-NN cable retention

SRC3-U5A1C1BD000 • SRC 100, black version, underground
MID: 760251028

- No adapters
- Splice only
- 24x SMOUV 45 splice
- No splitter
- 2x NVX-CR-SA-SM-NN cable retention

SRC3-U5A1B1BC000 • SRC 100, black version, underground
MID: 760251023

- No adapters
- Splice only
- 12x SMOUV 45 splice
- No splitter
- 2x NVX-CR-MC-RD-NN cable retention

SRC3-U5A1C1BE000 • SRC 100, black version, underground
MID: 760251029

- No adapters
- Splice only
- 24x SMOUV 45 splice
- No splitter
- 2x NVX-CR-TI-SM-NN cable retention

SRC3-U5A1B1BD000 • SRC 100, black version, underground
MID: 760251024

- No adapters
- Splice only
- 12x SMOUV 45 splice
- No splitter
- 2x NVX-CR-SA-SM-NN cable retention

SRC3-U5A1B1BB001 • SRC 100, black version, underground
MID: 760251030

- No adapters
- Splice only
- 12x SMOUV 45 splice
- No splitter
- 2x NVX-CR-MC-FT-NN cable retention, including Tone Wire Connector (100/pk 88823Y-000 FDSC-GATOR-TEL-SPLICE)

SRC3-U5A1B1BE000 • SRC 100, black version, underground
MID: 760251025

- No adapters
- Splice only
- 12x SMOUV 45 splice
- No splitter
- 2x NVX-CR-TI-SM-NN cable retention

SRC3-U5A1B1BA000 • SRC 100, black version, underground
MID: 760251084

- No adapters
- Splice only
- 12x SMOUV 45 splice
- No splitter
- No cable retention

SRC3-U5A1C1BB000 • SRC 100, black version, underground
MID: 760251026

- No adapters
- Splice only
- 24x SMOUV 45 splice
- No splitter
- 2x NVX-CR-MC-FT-NN cable retention

SRC3-U5A1C1BA000 • SRC 100, black version, underground
MID: 760251085

- No adapters
- Splice only
- 24x SMOUV 45 splice
- No splitter
- No cable retention

SRC3-U5A1C1BC000 • SRC 100, black version, underground
MID: 760251027

- No adapters
- Splice only
- 24x SMOUV 45 splice
- No splitter
- 2x NVX-CR-MC-RD-NN cable retention

CommScope pushes the boundaries of communications technology with game-changing ideas and ground-breaking discoveries that spark profound human achievement. We collaborate with our customers and partners to design, create and build the world's most advanced networks. It is our passion and commitment to identify the next opportunity and realize a better tomorrow. Discover more at commscope.com.

COMMSCOPE®

commscope.com

Visit our website or contact your local CommScope representative for more information.

© 2021 CommScope, Inc. All rights reserved.

Unless otherwise noted, all trademarks identified by ® or ™ are registered trademarks or trademarks, respectively, of CommScope, Inc. This document is for planning purposes only and is not intended to modify or supplement any specifications or warranties relating to CommScope products or services. CommScope is committed to the highest standards of business integrity and environmental sustainability, with a number of CommScope's facilities across the globe certified in accordance with international standards, including ISO 9001, TL 9000, and ISO 14001. Further information regarding CommScope's commitment can be found at www.commscope.com/corporate-responsibility-and-sustainability.

PA-115152.1-EN (04/21)