

DFJ-2S5-LCSC2-1M2

HELIAX® Discrete, 2 single mode fiber, 5 mm LSZH cable. End 1: DLC.
End 2: SC, length 1.2Meters



Product Classification

Portfolio	CommScope®
Product Type	Wireless Fiber Cable Assemblies
Product Brand	HELIAX®
Product Series	DFJ

General Specifications


Color, connector A	Blue
Color, connector B	Blue
Connector A, quantity	1
Connector B, quantity	2
Interface, Connector A	DLC
Interface, Connector B	SC/UPC
Jacket Color	Black

Dimensions

Breakout Length, connector A	181.864 mm 7.16 in
Breakout Length, connector B	381 mm 15 in
Diameter Over Jacket	5 mm 0.197 in

Ordering Tree

DFJ-2S5-EAS-10M

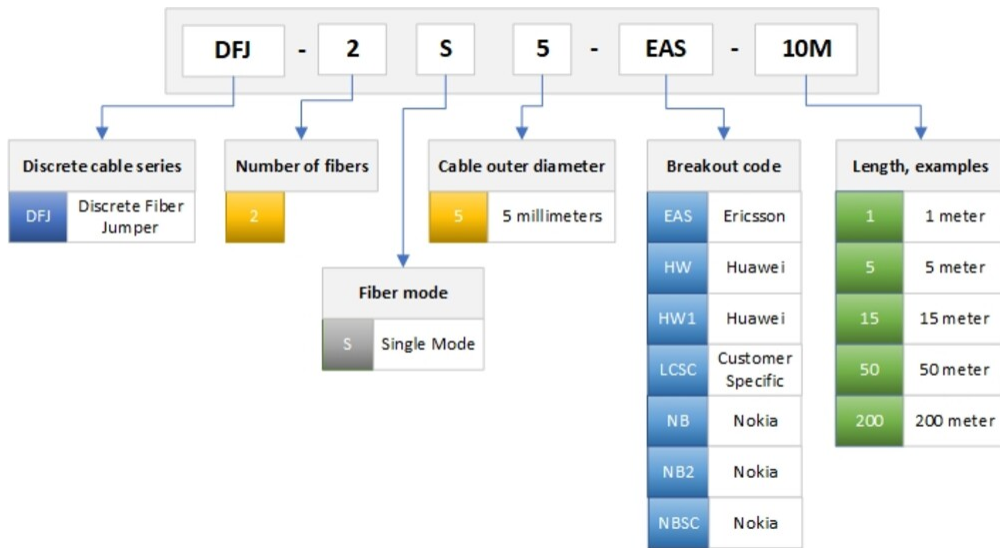

Optical Specifications

Fiber Mode Singlemode
Fiber Type G.657.A2

Environmental Specifications

Operating Temperature -40 °C to +80 °C (-40 °F to +176 °F)
Environmental Space Indoor | Outdoor

Regulatory Compliance/Certifications

Agency	Classification
CHINA-ROHS	Below maximum concentration value
REACH-SVHC	Compliant as per SVHC revision on www.commscope.com/ProductCompliance
ROHS	Compliant

