

## Pre-term Fiber Quick-Turn Program

---

The Quick-Turn Fiber program is designed to meet the needs of customers who have immediate requirements for fiber jumpers, MPO arrays and trunks. The Quick-Turn Fiber program is intended to supplement the current pre-term fiber provisioning process. This is a service provided to CommScope customers to address last minute pre-term fiber requirements, as well as fiber pre-term assemblies required to accommodate moves, adds, and changes.

### PLACE AN ORDER

- Orders are placed from distributor via email at [quickturn@commscope.com](mailto:quickturn@commscope.com)
- Maximum order quantity is 70 fiber jumpers and 20 trunks or arrays per order.
- Lead time target is 10 business days after receipt of order. Lead times may vary based on current capacity.
- For additional quantities, please call Customer Service.

### PRICING

- Quick-Turn fiber orders qualify for the same project pricing discount.

### SHIPPING

- Customer pays for shipping charges. Actual shipping time depends on the shipping option selected by the customer. Clear shipping instructions, including: ship to address, shipping options, and account number (FedEx, UPS, Etc.), must be included in the purchase order.



[quickturn@commscope.com](mailto:quickturn@commscope.com)


# Quick-Turn Product Listing

## Ultra Low-loss Jumpers

### JUMPERS

Choose your configuration, add length and quantities. Complete the MIDs in Column "A"

FULLY CONFIGURED MID	DESCRIPTION
A	B
<b>Ultra Low-loss Uniboot Jumpers (Uniboot LC- Uniboot LC)</b>	
UFXLULU62-MX_ _ _ _	ULL OM4 LC Uniboot to LC Uniboot , Fiber Patch Cord, 2.0 mm Duplex, Riser, Aqua
UDXLULU62-MX_ _ _ _	ULL OM4 LC Uniboot to LC Uniboot, Fiber Patch Cord, 2.0 mm Duplex, Plenum, Aqua
UFGLULU62-JX_ _ _ _	ULL Singlemode® LC Uniboot to LC Uniboot , Fiber Patch Cord, 2.0 mm Duplex, Plenum, Yellow
UDGLULU62-JX_ _ _ _	ULL Singlemode® LC Uniboot to LC Uniboot , Fiber Patch Cord, 2.0 mm Duplex, Riser, Yellow
<b>Ultra Low-loss Jumpers (duplex LC-LC)</b>	
UFXLCLC42-MX_ _ _ _	ULL OM4 LC to LC, Fiber Patch Cord, 1.6 mm Duplex, Riser, Aqua
UDXLCLC42-MX_ _ _ _	ULL OM4 LC to LC, Fiber Patch Cord, 1.6 mm Duplex, Plenum, Aqua
UDGLCLC42-JX_ _ _ _	ULL Singlemode® LC to LC, Fiber Patch Cord, 1.6 mm Duplex, Plenum, Yellow
UFGLCLC42-JX_ _ _ _	ULL Singlemode® LC to LC, Fiber Patch Cord, 1.6 mm Duplex, Riser, Yellow

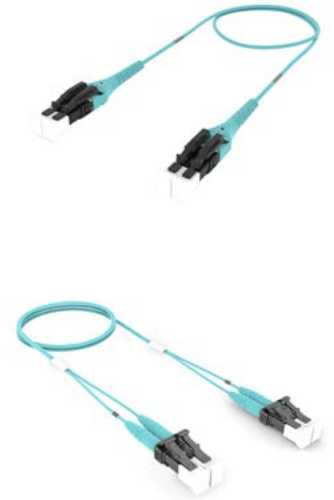

Email: [quickturn@commscope.com](mailto:quickturn@commscope.com)

# Quick-Turn Product Listing

## Ultra Low-loss Array Patchcords & Array Fanouts

### ARRAY PATCHCORDS

Choose your configuration, add length and quantities. Complete the MIDs in Column "A"

FULLY CONFIGURED MID	DESCRIPTION
A	B
<b>SYSTIMAX ULL Array Patchcords (unpinned MPO-unpinned MPO), Plenum</b>	
UQXMPMPGD-MA_ _ _ _	ULL OM4 MPO (non-pinned) to MPO (non-pinned), 12-Fiber, Plenum, Aqua
<b>SYSTIMAX ULL Array Patchcords (unpinned MPO-pinned MPO), Plenum</b>	
UQXMPMXGD-MA_ _ _ _	ULL OM4 MPO (non-pinned) to MPO (pinned), 12-Fiber, Plenum, Aqua
<b>SYSTIMAX ULL QSFP Arrays (unpinned MPO-8LC), Plenum</b>	
UQXQPLCJ8-MD_ _ _ _	ULL OM4 MPO (non-pinned) to LC, QSFP Array Cord, 8-Fiber, Plenum, Aqua, BO=12"
UQXQPLCJ8-ME_ _ _ _	ULL OM4 MPO (non-pinned) to LC, QSFP Array Cord, 8-Fiber, Plenum, Aqua, BO=24"
UQXQPLCJ8-MH_ _ _ _	ULL OM4 MPO (non-pinned) to LC, QSFP Array Cord, 8-Fiber, Plenum, Aqua, BO=48"
<b>SYSTIMAX ULL QSFP Arrays (pinned MPO-8LC), Plenum</b>	
UQXQXLCJ8-MD_ _ _ _	ULL OM4 MPO (pinned) to LC, QSFP Array Cord, 8-Fiber, Plenum, Aqua, BO=12"
UQXQXLCJ8-ME_ _ _ _	ULL OM4 MPO (pinned) to LC, QSFP Array Cord, 8-Fiber, Plenum, Aqua, BO=24"
UQXQXLCJ8-MH_ _ _ _	ULL OM4 MPO (pinned) to LC, QSFP Array Cord, 8-Fiber, Plenum, Aqua, BO=48"



### ARRAY FANOUTS

Choose your configuration, add length and quantities. Complete the MIDs in Column "A"

FULLY CONFIGURED MID	DESCRIPTION
A	B
<b>SYSTIMAX ULL Array Fanout (unpinned MPO-12LC), Plenum</b>	
UQXMPLCGD-MD_ _ _ _	ULL OM4 MPO (non-pinned) to LC, Array Fanout, 12-Fiber, Plenum, Aqua, BO=12"
UQXMPLCGD-ME_ _ _ _	ULL OM4 MPO (non-pinned) to LC, Array Fanout, 12-Fiber, Plenum, Aqua, BO=24"
UQXMPLCGD-MH_ _ _ _	ULL OM4 MPO (non-pinned) to LC, Array Fanout, 12-Fiber, Plenum, Aqua, BO=48"
<b>SYSTIMAX ULL Array Fanout (pinned MPO-12LC), Plenum</b>	
UQXMXLCGD-MD_ _ _ _	ULL OM4 MPO (pinned) to LC, Array Fanout, 12-Fiber, Plenum, Aqua, BO=12"
UQXMXLCGD-ME_ _ _ _	ULL OM4 MPO (pinned) to LC, Array Fanout, 12-Fiber, Plenum, Aqua, BO=24"
UQXMXLCGD-MH_ _ _ _	ULL OM4 MPO (pinned) to LC, Array Fanout, 12-Fiber, Plenum, Aqua, BO=48"



Email: [quickturn@commscope.com](mailto:quickturn@commscope.com)


# Quick-Turn Product Listing

## Ultra Low-loss Trunk Cables

### TRUNK CABLES

Choose your configuration, add length and quantities. Complete the MIDs in Column "A"

FULLY CONFIGURED MID	DESCRIPTION
A	B
<b>SYSTIMAX ULL Pre-terminated Trunk Cable, Plenum with Gland Option</b>	
UGXMXMXCD-MB_ _ _ _	ULL OM4 MPO (pinned) to MPO (pinned), 12-Fiber, Plenum, Aqua
UGXMXMXCF-MB_ _ _ _	ULL OM4 MPO (pinned) to MPO (pinned), 24-Fiber, Plenum, Aqua
UGXMXMXCG-MB_ _ _ _	ULL OM4 MPO (pinned) to MPO (pinned), 36-Fiber, Plenum, Aqua
UGXMXMXCH-MB_ _ _ _	ULL OM4 MPO (pinned) to MPO (pinned), 48-Fiber, Plenum, Aqua
UGGMXMXCD-JB_ _ _ _	ULL Singlemode MPO (pinned) to MPO (pinned), 12-Fiber, Plenum, Yellow
UGGMXMXCF-JB_ _ _ _	ULL Singlemode® MPO (pinned) to MPO (pinned), 24-Fiber, Plenum, Yellow
UGGMXMXCG-JB_ _ _ _	ULL Singlemode® MPO (pinned) to MPO (pinned), 36-Fiber, Plenum, Yellow
UGGMXMXCH-JB_ _ _ _	ULL Singlemode® MPO (pinned) to MPO (pinned), 48-Fiber, Plenum, Yellow
<b>SYSTIMAX ULL Pre-terminated Trunk Cable, Plenum without Gland Option</b>	
UGXMXMXCD-MA_ _ _ _	ULL OM4 MPO (pinned) to MPO (pinned), 12-Fiber, Plenum, Aqua
UGXMXMXCF-MA_ _ _ _	ULL OM4 MPO (pinned) to MPO (pinned), 24-Fiber, Plenum, Aqua
UGXMXMXCG-MA_ _ _ _	ULL OM4 MPO (pinned) to MPO (pinned), 36-Fiber, Plenum, Aqua
UGXMXMXCH-MA_ _ _ _	ULL OM4 MPO (pinned) to MPO (pinned), 48-Fiber, Plenum, Aqua
UGGMXMXCD-JA_ _ _ _	ULL Singlemode MPO (pinned) to MPO (pinned), 12-Fiber, Plenum, Yellow
UGGMXMXCF-JA_ _ _ _	ULL Singlemode MPO (pinned) to MPO (pinned), 24-Fiber, Plenum, Yellow
UGGMXMXCG-JA_ _ _ _	ULL Singlemode MPO (pinned) to MPO (pinned), 36-Fiber, Plenum, Yellow
UGGMXMXCH-JA_ _ _ _	ULL Singlemode MPO (pinned) to MPO (pinned), 48-Fiber, Plenum, Yellow
<b>SYSTIMAX ULL Pre-terminated Trunk Cable, Plenum with Gland Option AND Pulling Grip</b>	
UGXMXMXCD-MC_ _ _ _	ULL OM4 MPO (pinned) to MPO (pinned), 12-Fiber, Plenum, Aqua
UGXMXMXCF-MC_ _ _ _	ULL OM4 MPO (pinned) to MPO (pinned), 24-Fiber, Plenum, Aqua
UGXMXMXCG-MC_ _ _ _	ULL OM4 MPO (pinned) to MPO (pinned), 36-Fiber, Plenum, Aqua
UGXMXMXCH-MC_ _ _ _	ULL OM4 MPO (pinned) to MPO (pinned), 48-Fiber, Plenum, Aqua
UGGMXMXCD-JC_ _ _ _	ULL Singlemode MPO (pinned) to MPO (pinned), 12-Fiber, Plenum, Yellow
UGGMXMXCF-JC_ _ _ _	ULL Singlemode MPO (pinned) to MPO (pinned), 24-Fiber, Plenum, Yellow
UGGMXMXCG-JC_ _ _ _	ULL Singlemode MPO (pinned) to MPO (pinned), 36-Fiber, Plenum, Yellow
UGGMXMXCH-JC_ _ _ _	ULL Singlemode MPO (pinned) to MPO (pinned), 48-Fiber, Plenum, Yellow

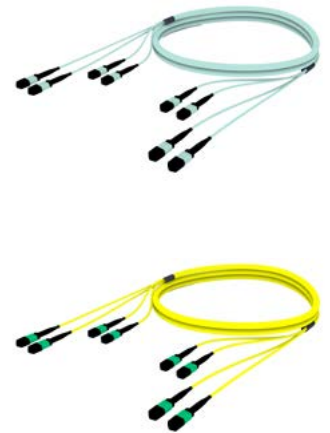

Email: [quickturn@commscope.com](mailto:quickturn@commscope.com)


# Quick-Turn Product Listing

## Low-loss Jumpers

### JUMPERS

Choose your configuration, add length and quantities. Complete the MIDs in Column "A"

FULLY CONFIGURED MID	DESCRIPTION
A	B
<b>Low-loss Jumpers (duplex LC-LC)</b>	
FEXLCLC42-MX_ _ _ _	LazrSPEED® 550 LC to LC, Fiber Patch Cord, 1.6 mm Duplex, Riser, Aqua
FDXLCLC42-MX_ _ _ _	LazrSPEED® 550 LC to LC, Fiber Patch Cord, 1.6 mm Duplex, Plenum, Aqua
FDWLCLC42-JX_ _ _ _	TeraSPEED® LC to LC, Fiber Patch Cord, 1.6 mm Duplex, Plenum, Yellow
FEWLCLC42-JX_ _ _ _	TeraSPEED® LC to LC, Fiber Patch Cord, 1.6 mm Duplex, Riser, Yellow

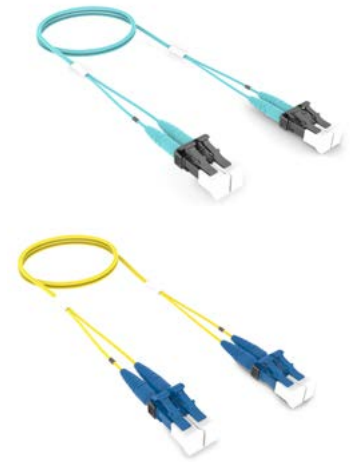

Email: [quickturn@commscope.com](mailto:quickturn@commscope.com)

# Quick-Turn Product Listing

## Low-loss Array Patchcords

### ARRAY PATCHCORDS

Choose your configuration, add length and quantities. Complete the MIDs in Column "A"

FULLY CONFIGURED MID	DESCRIPTION
A	B
InstaPATCH® 360 Array Patchcords (unpinned MPO-unpinned MPO), Plenum	
FQXMPMPGD-MA_ _ _ _	LazrSPEED® 550 MPO (non-pinned) to MPO (non-pinned), 12-Fiber, Plenum, Aqua
InstaPATCH® 360 Array Patchcords (unpinned MPO-pinned MPO), Plenum	
FQXMPMXGD-MA_ _ _ _	LazrSPEED® 550 MPO (non-pinned) to MPO (male), 12-Fiber, Plenum, Aqua



Email: [quickturn@commscope.com](mailto:quickturn@commscope.com)

# Quick-Turn Product Listing

## Low-loss Trunk Cables

### TRUNK CABLES

Choose your configuration, add length and quantities. Complete the MIDs in Column "A"

FULLY CONFIGURED MID	DESCRIPTION
A	B
<b>InstaPATCH® 360 Pre-terminated Trunk Cable, Plenum with Gland Option</b>	
FGXMPMPAD-MB_ _ _ _	LazrSPEED® 550 MPO (non-pinned) to MPO (non-pinned), 12-Fiber, Plenum, Aqua
FGXMPMPAF-MB_ _ _ _	LazrSPEED® 550 MPO (non-pinned) to MPO (non-pinned), 24-Fiber, Plenum, Aqua
FGXMPMPAG-MB_ _ _ _	LazrSPEED® 550 MPO (non-pinned) to MPO (non-pinned), 36-Fiber, Plenum, Aqua
FGXMPMPAH-MB_ _ _ _	LazrSPEED® 550 MPO (non-pinned) to MPO (non-pinned), 48-Fiber, Plenum, Aqua
<b>InstaPATCH® 360 Pre-terminated Trunk Cable, Plenum with Gland Option</b>	
FGXMPMPAD-MA_ _ _ _	LazrSPEED® 550 MPO (non-pinned) to MPO (non-pinned), 12-Fiber, Plenum, Aqua
FGXMPMPAF-MA_ _ _ _	LazrSPEED® 550 MPO (non-pinned) to MPO (non-pinned), 24-Fiber, Plenum, Aqua
FGXMPMPAG-MA_ _ _ _	LazrSPEED® 550 MPO (non-pinned) to MPO (non-pinned), 36-Fiber, Plenum, Aqua
FGXMPMPAH-MA_ _ _ _	LazrSPEED® 550 MPO (non-pinned) to MPO (non-pinned), 48-Fiber, Plenum, Aqua
<b>InstaPATCH® 360 Pre-terminated Trunk Cable, Plenum with Gland Option AND Pulling Grip</b>	
FGXMPMPAD-MC_ _ _ _	LazrSPEED® 550 MPO (non-pinned) to MPO (non-pinned), 12-Fiber, Plenum, Aqua
FGXMPMPAF-MC_ _ _ _	LazrSPEED® 550 MPO (non-pinned) to MPO (non-pinned), 24-Fiber, Plenum, Aqua
FGXMPMPAG-MC_ _ _ _	LazrSPEED® 550 MPO (non-pinned) to MPO (non-pinned), 36-Fiber, Plenum, Aqua
FGXMPMPAH-MC_ _ _ _	LazrSPEED® 550 MPO (non-pinned) to MPO (non-pinned), 48-Fiber, Plenum, Aqua



Email: [quickturn@commscope.com](mailto:quickturn@commscope.com)

# Shipping guidelines

---

## SHIPPING

- The customer pays shipping charges.
- Clear shipping instructions, including: ship to address, shipping options, and account number (FedEx, UPS, Etc.), must be included in the purchase order.

## ADDITIONAL SHIPPING LOGISTICS

- Suggestion for Customer carrier request questions: (US ship from to US destination)
  - FedEx Small Parcel – requires carrier account (9 digit #), is it a recipient or third party account and service level of one of each of the following service levels: Priority Overnight, Standard Overnight, FedEx 2 day, FedEx Express Saver.
  - FedEx Air Freight – on larger orders, ask up front if customer has a weight limit or limit of quantity of cartons before requiring palletization. If shipment requires air freight service, request carrier, valid air freight account (9 digit #), is it a recipient or third party account, and one of the following service levels: FedEx 1 Day Air Freight, FedEx 2 Day Air Freight, FedEx 3 Day Air Freight.
  - UPS (Brown) Small parcel - require carrier account (6 digit, usually alpha numeric), is it a recipient or third party account, bill to zip code for third party account (sometimes required for UPS to create label if consignee zip is different than bill to account zip) and service level of one of each of the following service levels: UPS Next Day Air, UPS 2nd day Air, UPS 3 Day Select.
  - UPS Supply Chain Solutions (UPS Air Freight division) - require carrier account (9 digit), bill to zip code for account (sometimes required for UPS to create label if consignee zip is different than bill to account zip) and service level of one of each of the following service levels: UPS Next Day Air Freight, UPS 2nd Day Air Freight, UPS 3 Day Air Freight.

	<b>CARTON</b>	<b>SPOOL</b>	<b>WOODED REEL</b>	<b>WEIGHT 1000 FT.</b>
12 Fiber	<=130 Ft.	131-999 Ft.	>1000 Ft.	20 lbs.
24 Fiber	<=100 Ft.	101-999 Ft.	>1000 Ft.	25 lbs.
48 Fiber	<=100 Ft.	101-999 Ft.	>1000 Ft.	60 lbs.
96 Fiber	<=100 Ft.	085-500 Ft.	>500 Ft.	60 lbs. @ 501 Ft.
144 Fiber	<=65 Ft.	066-265 Ft.	>266 Ft.	60 lbs. @ 266 Ft.

- The guide on length limits will keep the size of packaging required to hold product within a small parcel transportation category. If customer orders various lengths, customer may receive multiple small cartons. This is a packaging question based upon vendor capability.
- Black spool dimensions are: 15in. X 9.25 in. X 15in.
- Small wooden reel dimensions are: 24.75 in. X 12.25 in. X 24.75 in.
- Black Plastic Spool or Small Wooden reel **\*\*310 Wooden reel\*\*** increment length limit before Air Freight is required
- 310 wooden reel cannot be shipped small parcel. It would be required to be placed on a pallet and AIR FREIGHT division information would be required from customer at time SO is placed.

Email: [quickturn@commscope.com](mailto:quickturn@commscope.com)

---



CommScope pushes the boundaries of communications technology with game-changing ideas and ground-breaking discoveries that spark profound human achievement. We collaborate with our customers and partners to design, create and build the world's most advanced networks. It is our passion and commitment to identify the next opportunity and realize a better tomorrow. Discover more at [commscope.com](https://commscope.com)

---

[commscope.com](https://commscope.com)

Visit our website or contact your local CommScope representative for more information.

© 2019 CommScope, Inc. All rights reserved.

Unless otherwise noted, all trademarks identified by ® or ™ are registered trademarks, respectively, of CommScope, Inc. This document is for planning purposes only and is not intended to modify or supplement any specifications or warranties relating to CommScope products or services. CommScope is committed to the highest standards of business integrity and environmental sustainability with a number of CommScope's facilities across the globe certified in accordance with international standards, including ISO 9001, TL 9000, and ISO 14001. Further information regarding CommScope's commitment can be found at [www.commscope.com/About-Us/Corporate-Responsibility-and-Sustainability](https://www.commscope.com/About-Us/Corporate-Responsibility-and-Sustainability).